

Features

- 1 Space saving : 0.7mm stacking height, 2.5mm width
- 2 Robust design with metal solder tabs and ample housing thickness
- 3 Highly reliable 2-point contact design
- 4 Easy mating operation with clear tactile click and wide self alignment range
- 5 Wide vacuum pick & place area with 2.5mm width
- 6 Solder wicking prevention and contact protection against dust



Space Saving




Robust




High Reliability

Highly Reliable Contact Design

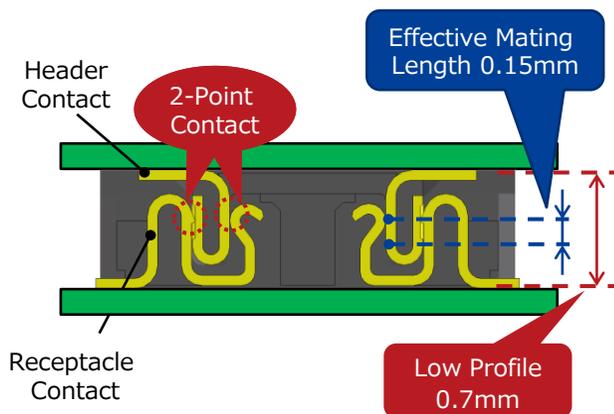

Robust Design

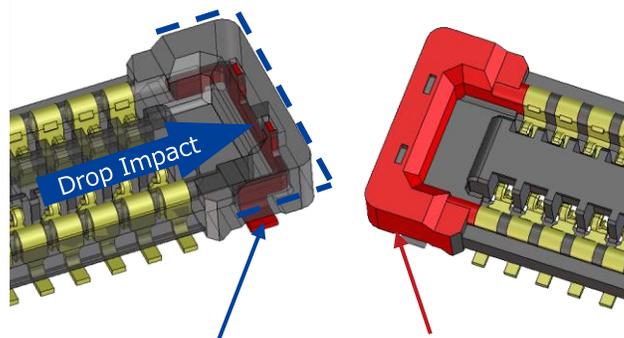

Metal solder tabs absorb the stress by drop impact

Ample housing thickness minimizes damage

Specifications

Rated Current	0.3A
Rated Voltage	30V AC
Operating Temperature	-55 to +85°C*
Contact Resistance	100mΩ Max. (20mV AC, 1kHz, 1mA)
Withstanding Voltage	100V AC for 1 min.
Insulation Resistance	50MΩ Min. (100V DC)

* Includes the temperature rise by current flow.

•Variations: 16, 24pos.