

### Features


- 1 Ultra Low profile 1.15mm height
- 2 Prevents incorrect card insertion
- 3 Excellent card lock mechanism
- 4 Prevents mis card insertion
- 5 Card detection switch (Normally close)




The world's lowest profile in its Class 1.15 mm\*

\* As push-push type micro SD™ connector as of June 2016.


### Dimensions

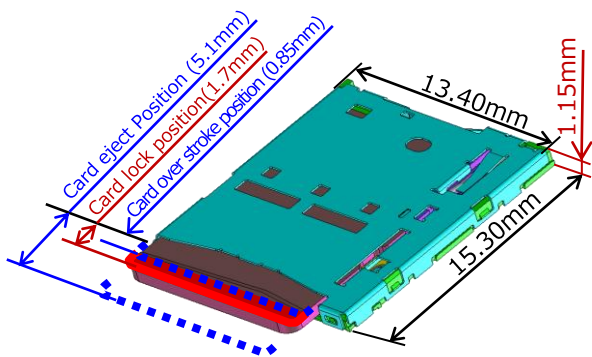

### Prevents card jamming if nano SIM inserted

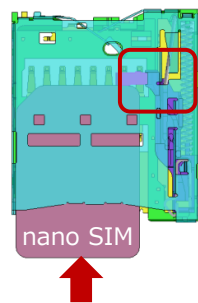

Easy to remove the card when accidentally inserted

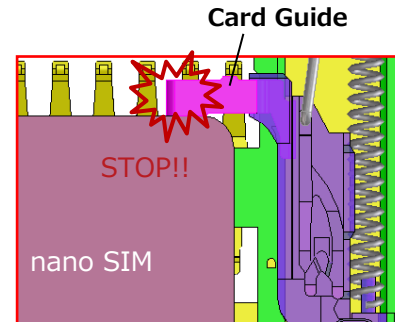

### Specifications

Rated Current	0.5A
Rated Voltage	10V AC
Operating Temperature	-30°C to +85°C
Contact Resistance	60mΩ Max. (Signal) 200mΩ Max. (Detection)
Withstanding Voltage	500V AC for 1 minute
Insulation Resistance	1,000MΩ Min. (500V DC)
Mating Durability	10,000 times

• RoHS compliant, Halogen-free product\*

\*This product satisfies halogen free requirements defined as 900ppm maximum chlorine, 900ppm maximum bromine, and 1,500ppm maximum total of chlorine and bromine

※ Please contact Hirose's sales representative prior to adopting the products to in-vehicle devices.