 



Features


- 1 Space saving : 0.7mm stacking height, 2.5mm width
- 2 Robust design with metal solder tabs and ample housing thickness
- 3 Highly reliable 2-point contact design
- 4 Easy mating operation with clear tactile click and wide self alignment range
- 5 Wide vacuum pick & place area with 2.5mm width
- 6 Solder wicking prevention and contact protection against dust



Highly reliable contact design

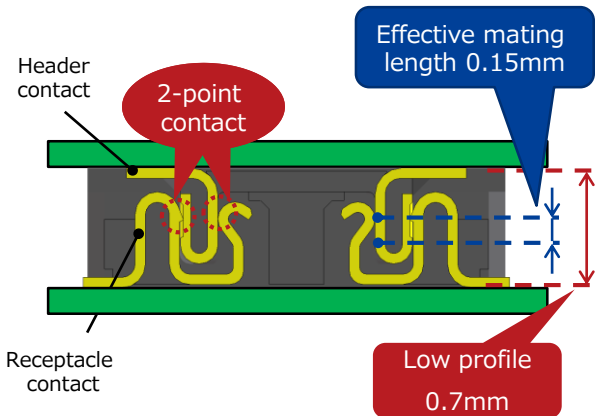

Robust design

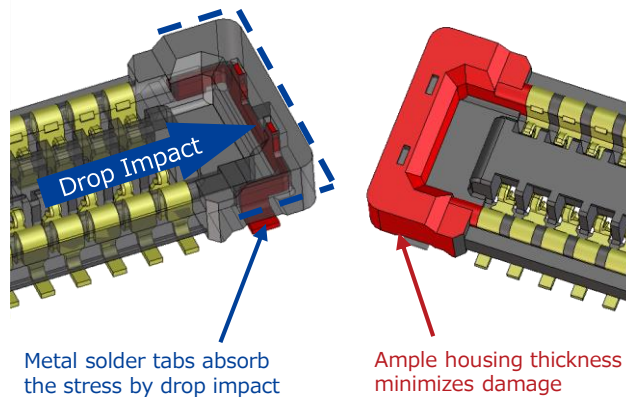

Specifications

Rated Current	0.3A
Rated Voltage	30V AC
Operating Temperature	-55 to +85°C*
Contact Resistance	100mΩ Max. (20mV AC, 1kHz, 1mA)
Withstanding Voltage	100V AC for 1 minute
Insulation Resistance	50MΩ Min. (100V DC)

* Includes the temperature rise by current flow.

•Variations: 16, 24 pos.