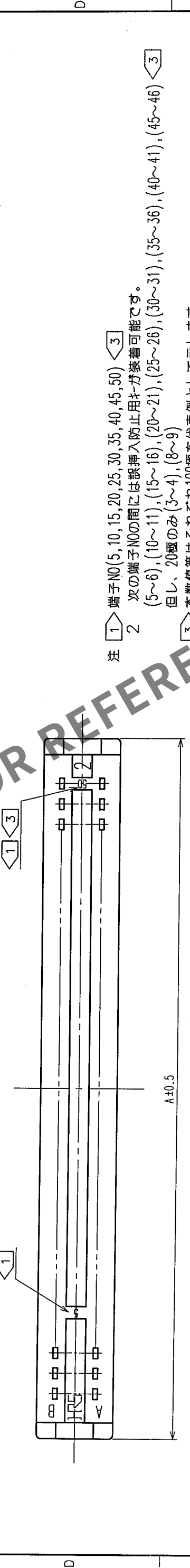



 $A \pm 0.5$

[illegible]

U	U
---	---

522-0014-3-70	CR22A-60D-2.54DS(70)	60	84.84	78.74	73.66	60.96	65.94
522-0016-9-70	CR22A-62D-2.54DS(70)	62	87.38	81.28	76.20	60.96	65.94
522-0018-4-70	CR22A-68D-2.54DS(70)	68	95.00	88.90	83.82	60.96	65.94
522-0020-6-70	CR22A-72D-2.54DS(70)	72	100.08	93.98	88.90	60.96	65.94
522-0050-7-70	CR22A-80D-2.54DS(70)	80	110.24	104.14	99.06	60.96	65.94
522-0006-5-70	CR22A-100D-2.54DS(70)	100	135.64	129.54	124.46	60.96	65.94