 



Features


- 1 Space saving : 0.7mm stacking height, 2.5mm width
- 2 Robust design with metal solder tabs and ample housing thickness
- 3 Highly reliable 2-point contact design
- 4 Easy mating operation with clear tactile click and wide self alignment range
- 5 Wide vacuum pick & place area with 2.5mm width
- 6 Solder wicking prevention and contact protection against dust



Highly Reliable Contact Design

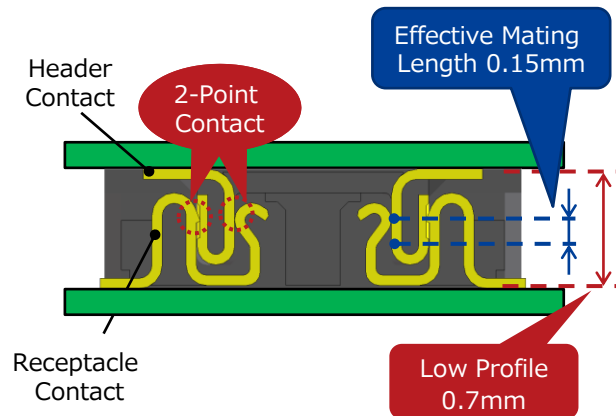

Robust Design

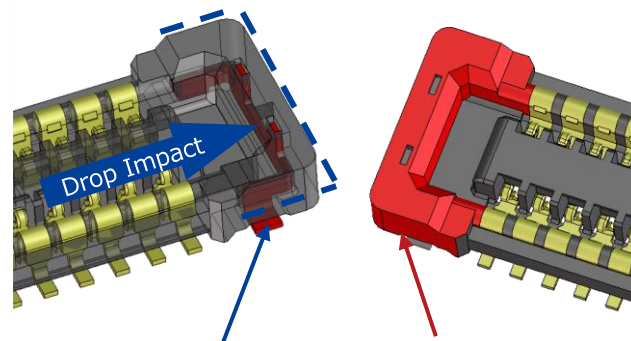

Metal solder tabs absorb the stress by drop impact

Ample housing thickness minimizes damage

Specifications

| | |
|-----------------------|------------------------------------|
| Rated Current | 0.3A |
| Rated Voltage | 30V AC |
| Operating Temperature | -55 to +85°C* |
| Contact Resistance | 100mΩ Max. (20mV AC, 1kHz, 1mA) |
| Withstanding Voltage | 100V AC for 1 min. |
| Insulation Resistance | 50MΩ Min. (100V DC) |

* Includes the temperature rise by current flow.

•Variations: 16, 24pos.