


Features


- 1 **Slim & low-profile 1 pole connector optimized for LED lighting applications**
- 2 **Long and effective mating length : 1.3mm**
- 3 **Floating design**
- 4 **Secured mating with clear tactile click**
- 5 **High current capability : 3A**

Dimensions

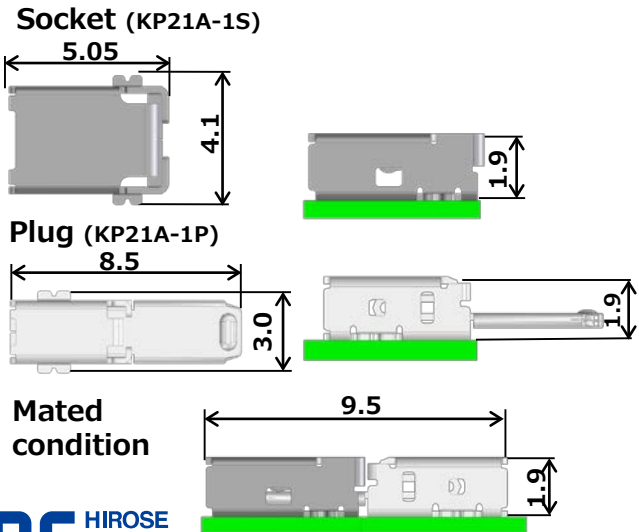

Floating Design (XYZ direction)

Position shift absorbing design ensuring contact reliability

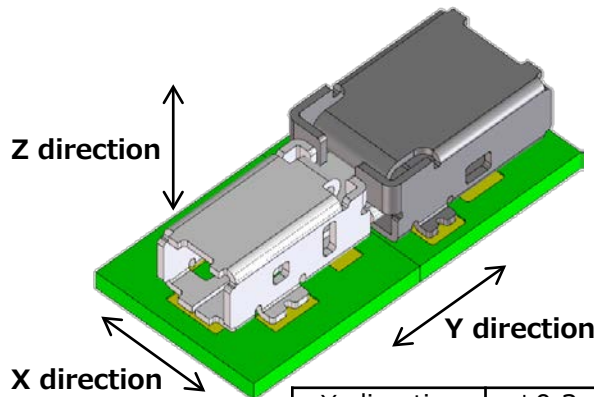

X direction	±0.3mm
Y direction	±0.2mm
Z direction	±0.5mm

Specifications

Contact Resistance	20mΩ Max.
Rated Current	3A
Rated Voltage	125V AC
Operating Temperature	-55°C to +85°C
Durability	10 times

- RoHS compliant, Halogen-free product*

*This product satisfies halogen free requirements defined as 900ppm maximum chlorine, 900ppm maximum bromine, and 1500ppm maximum total of chlorine and bromine.