

### Features

- 1 IP67 waterproof and weather resistant RJ-45 LAN connector cover for outdoor use
- 2 Compatible with board mounted RJ-45 jack LAN
- 3 Absorbs assembly tolerance up to  $\pm 1\text{mm}$
- 4 Double lock design prevents incorrect wiring
- 5 High cable clamp strength


### Compatible with Existing RJ-45 LAN Connectors

### IP67 & Weather Resistance Performance Without Having to Change the RJ-45 LAN Connector

- IP67 Water Resistance
- Weather Resistant Plastic Materials for Outdoor Use
- Robust Bayonet Lock



### Dimensions

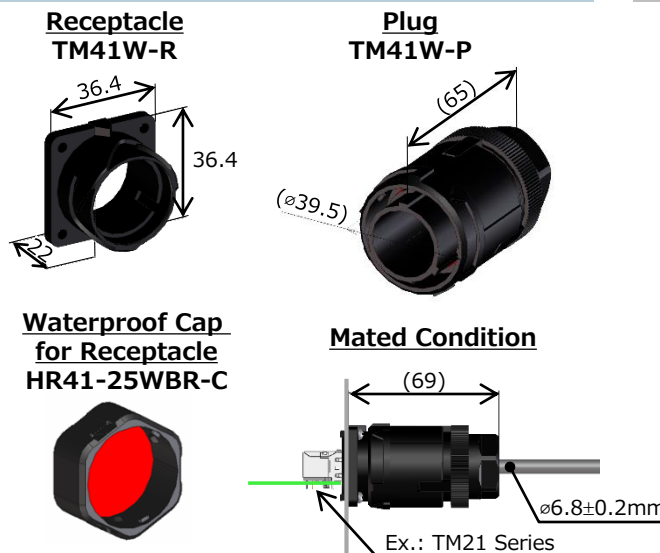

### Specifications

Operating Temperature	Plug	-25 to +60°C (Includes the temperature rise due to current flow.)
	Receptacle	-55 to +85°C (Includes the temperature rise due to current flow.)
Storage Temperature	-25 to +60°C	
Mating Durability	100 times (Bayonet Lock)	
Waterproof	IP67	

- RoHS compliant