

Weather Resistant RJ-45 LAN Connector Hood




Waterproof



Harsh Environment



Bayonet

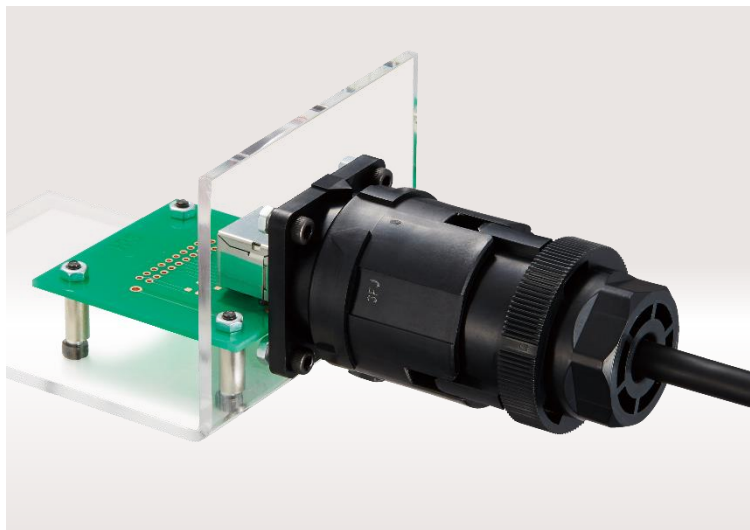

Features

- 1 IP67 waterproof and weather resistant RJ-45 LAN connector cover for outdoor use
- 2 Compatible with board mounted RJ-45 jack LAN
- 3 Absorbs assembly tolerance up to $\pm 1\text{mm}$
- 4 Double lock design prevents incorrect wiring
- 5 High cable clamp strength


Compatible with Existing RJ-45 LAN Connectors

IP67 & Weather Resistance Performance Without Having to Change the RJ-45 LAN Connector

- IP67 Water Resistance
- Weather Resistant Plastic Materials for Outdoor Use
- Robust Bayonet Lock



Dimensions

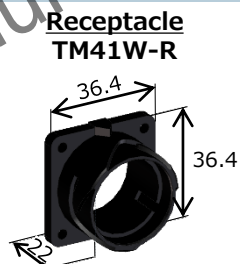


Waterproof Cap for Receptacle

HR41-25WBR-C



Mated Condition

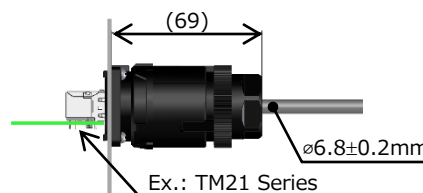

Specifications

Operating Temperature	Plug	-25 to +60°C (Includes the temperature rise due to current flow.)
	Receptacle	-55 to +85°C (Includes the temperature rise due to current flow.)
Storage Temperature		-25 to +60°C
Mating Durability		100 times (Bayonet Lock)
Waterproof		IP67

- RoHS compliant